

Price List Addendum

EFFECTIVE May 27, 2026

VicFlex™ Preassembled System

SELECT ADAPTER AND SPRINKLER COMBINATION, THEN MAKE BRAIDED HOSE SELECTION. SPRINKLER/ ADAPTER SUB-ASSEMBLY WILL SHIP SEPARATELY FROM BRAIDED HOSE

Additional configurations of sprinkler and adapter can be configured on following page.

Adapter	Sprinkler	Temperature	Finish	Victaulic Part No.	Price Each
Straight – 5.5"	V2708	155F	Chrome	A271BCQ42G	\$78.00
	V2708	155F	White	A271BCQ44G	78.00
	V2708	200F	Chrome	A271BFQ42G	78.00
	V2708	200F	White	A271BFQ44G	78.00
	V3802	155F	Brass	A381PCQ41G	86.00
	V4906	155F	Brass	A491NCQH1G	91.00
	V5606	155F	Brass	A566PCQ41G	91.00
Low Profile Elbow	V5606	200F	Brass	A566PFQ41G	91.00
	V4906	155F	Brass	A491NCQH1S	95.00
	V5606	155F	Brass	A566PCQ41S	95.00

NOTE: Items listed in shaded areas are non-cancellable and non-returnable.


VicFlex™ Hose	Length Inches	Victaulic Part No.	Price Each
Series AH1	31	A310AQB10	\$56.50
	36	A360AQB10	59.50
	48	A480AQB10	78.00
	60	A600AQB10	93.00
	72	A720AQB10	100.00
Series AH1-CC	31	A310AQB1C	60.50
	36	A360AQB1C	63.50
	48	A480AQB1C	82.00
	60	A600AQB1C	97.00
	72	A720AQB1C	104.00
Series AH2	31	A310AQB20	65.00
	36	A360AQB20	69.50
	48	A480AQB20	89.50
	60	A600AQB20	111.50
	72	A720AQB20	122.00
Series AH2-CC	31	A310AQB2C	69.00
	36	A360AQB2C	73.50
	48	A480AQB2C	93.50
	60	A600AQB2C	115.50
	72	A720AQB2C	126.00
Series AH2-300	31	A310AQB30	78.00
	36	A360AQB30	83.50
	48	A480AQB30	107.50
	60	A600AQB30	134.00
	72	A720AQB30	146.50
Series AH2-CC-300	31	A310AQB3C	83.00
	36	A360AQB3C	88.50
	48	A480AQB3C	112.50
	60	A600AQB3C	139.00
	72	A720AQB3C	151.50

NOTE: Items listed in shaded areas are non-cancellable and non-returnable.

VicFlex™ Preassembled System Order Form

Bill To:

Company Name	
Address	
State/Province	Zip Code/Postal Code
Phone No.	Email
Fax No.	

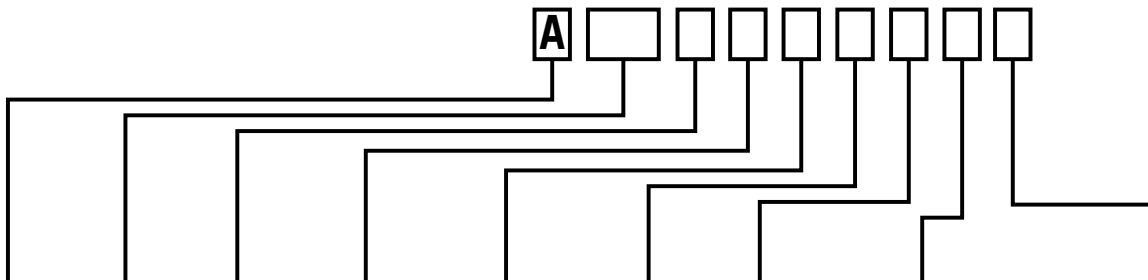

Sprinkler Selection								Hose/Bracket Selection
Class	Sprinkler Frame	Sprinkler Thread	Deflector Style	Sprinkler Temperature	Sprinkler Response	Sprinkler K-Factor	Sprinkler Finish	Reducer (outlet)
<input type="checkbox"/> A - VicFlex™	<input type="checkbox"/> 27 - V27 <input type="checkbox"/> 31 - V31 <input type="checkbox"/> 34 - V34 <input type="checkbox"/> 38 - V38 <input type="checkbox"/> 49 - V49 <input type="checkbox"/> 56 - V56 <input type="checkbox"/> 11 - V11	<input type="checkbox"/> 1 - ½" NPT <input type="checkbox"/> 2 - ¾" NPT	<input type="checkbox"/> B - STD PEND <input type="checkbox"/> G - ECLH PEND <input type="checkbox"/> J - ECLH CNC <input type="checkbox"/> K - RES PEND <input type="checkbox"/> N - RES CNC <input type="checkbox"/> C - HSW <input type="checkbox"/> P - CNCL PEN <input type="checkbox"/> F - ECOH PEN	<input type="checkbox"/> C - 155°F/68°C <input type="checkbox"/> E - 175°F/79°C <input type="checkbox"/> F - 200°F/93°C	<input type="checkbox"/> S - Standard <input type="checkbox"/> Q - Quick	<input type="checkbox"/> H - 4.9 <input type="checkbox"/> 4 - 5.6 <input type="checkbox"/> 5 - 8.0 <input type="checkbox"/> 6 - 11.2 <input type="checkbox"/> 7 - 14.0	<input type="checkbox"/> 1 - Plain Brass <input type="checkbox"/> 2 - Chrome <input type="checkbox"/> 4 - White (RAL 9010) <input type="checkbox"/> W - Bright White (RAL 9003) <input type="checkbox"/> N - VC250 ¹ <input type="checkbox"/> B - Black (RAL 9004)	<input type="checkbox"/> G - 5¾" Straight <input type="checkbox"/> 9 - 9" Straight <input type="checkbox"/> 3 - 13" Straight <input type="checkbox"/> P - 4¾" Elbow <input type="checkbox"/> E - 6¼" Elbow <input type="checkbox"/> S - Short Low Profile Elbow <input type="checkbox"/> L - Long Low Profile Elbow

¹ UL and FM approved corrosion resistant coating, and VdS and LPCB recognized and approved alternate coating. Appears chrome in color. Escutcheons for recessed sprinklers will match color of sprinkler. When VC-250 is selected, stainless steel escutcheons will be used.

* Recessed Escutcheons are supplied with Made On Head Assembly. Finish will match the Sprinkler Head.