

# Price List Addendum

EFFECTIVE June 15, 2026



PL2026-SD-ADD1


## Series FL-QR/C V3802

**QUICK RESPONSE ‡ –  
ADJUSTABLE CONCEALED  
K5.6 (8.1 SI)**

**Standard Pendant**  
½" NPT (15 mm BSPT) Thread  
½" (13 mm) Orifice  
Refer to publication 41.03.



Sprinkler and  
Cover

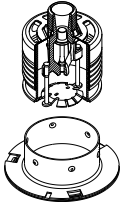

Sprinkler  
Cover



Temp. Rating		Victaulic Part Number	Standard Concealed	Finish	Price Each
°F	°C				
<b>ORDINARY TEMPERATURE</b>					
135	57	S381PAQ410	Sprinkler Only	Plain	\$71.50
155	68	S381PCQ410	Sprinkler Only	Plain	71.50 <sup>NR</sup>
135 *	57 *	S3806AS030	Cover Only	Bright Brass	14.50
135 *	57 *	S3806AS0D0	Cover Only	Brushed Brass	14.50
135 *	57 *	S3806AS020	Cover Only	Chrome	14.50 <sup>NR</sup>
135 *	57 *	S3806AS0C0	Cover Only	Brushed Chrome	14.50 <sup>NR</sup>
135 *	57 *	S3806AS040	Cover Only	White	14.50 <sup>NR</sup>
135 *	57 *	S3806AS0W0	Cover Only	Bright White	14.50 <sup>NR</sup>
135 *	57 *	S3806AS0G0	Cover Only	Cream	14.50
135 *	57 *	S3806AS0B0	Cover Only	Black	29.00 <sup>NR</sup>
135 *	57 *	S3806AS0_0	Cover Only	Custom ‡	+
<b>INTERMEDIATE TEMPERATURE</b>					
175	79	S381PEQ410	Sprinkler Only	Plain	\$71.50 <sup>NR</sup>
200	93	S381PFQ410	Sprinkler Only	Plain	71.50 <sup>NR</sup>
165 †	74 †	S3806D0030	Cover Only	Bright Brass	14.50
165 †	74 †	S3806D00D0	Cover Only	Brushed Brass	14.50
165 †	74 †	S3806D0020	Cover Only	Chrome	14.50 <sup>NR</sup>
165 †	74 †	S3806D00C0	Cover Only	Brushed Chrome	14.50
165 †	74 †	S3806D0040	Cover Only	White	14.50 <sup>NR</sup>
165 †	74 †	S3806D00W0	Cover Only	Bright White	14.50 <sup>NR</sup>
165 †	74 †	S3806D00G0	Cover Only	Cream	14.50
165 †	74 †	S3806D00B0	Cover Only	Black	29.00 <sup>NR</sup>
165 †	74 †	S3806D00_0	Cover Only	Custom ‡	+

+ Quoted on application. Contact Victaulic for pricing and availability.

**Recommended Wrenches:** V38-4 Socket Concealed; V38-5 Cabinet Socket. See Accessories for part number and price.

\* For use with Standard or Quick Response Concealed Sprinkler 135°F/57°C or 155°F/68°C

† For use with Standard or Quick Response Concealed Sprinkler 175°F/79°C or 200°F/93°C

‡ Customer must provide finish specification. Allow 4 weeks for samples.

<sup>NR</sup> Non-Returnable

### OPTIONAL CLEAN ROOM COVER SEAL GASKET FOR MODELS V3801 AND V3802

Victaulic Part Number	Price Each	Sold in Bag Quantities Of
S380P00000	\$16.00 <sup>NR</sup>	10

<sup>NR</sup> Non-Returnable

Items listed in shaded areas and custom finishes are non-cancellable and non-returnable.  
Unopened, full boxes of standard product less than two years old will be accepted for return.

### TERMS AND CONDITIONS OF SALE

Victaulic published Terms and Conditions of Sale listed in General Price List will apply. Prices, Designs and Conditions of Sale are subject to change without notice.

4901 Kesslersville Road, Easton, PA 18040 • 1-800-PICK-VIC (1-800-742-5842) • 1-610-250-8817 (fax) • pickvic@victaulic.com

